


BICSI Pattern Telecommunications Ground Bar Kits

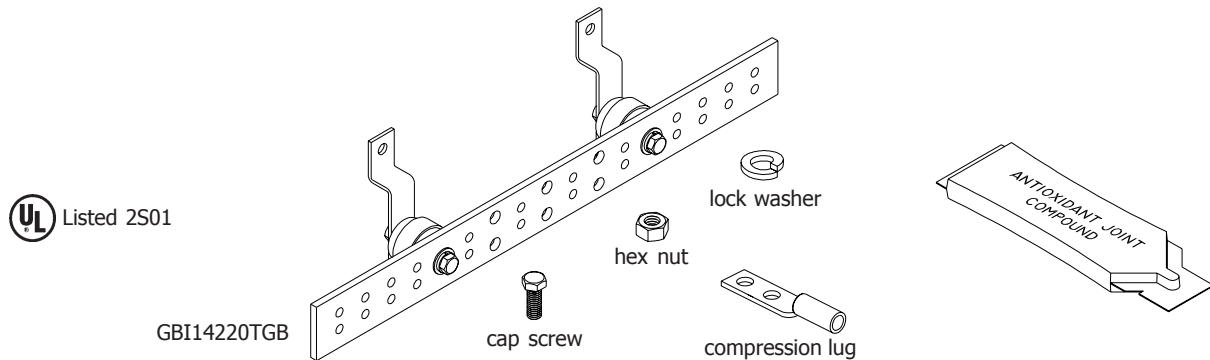

Part No.	Bar Size	Material	No. of 5/16" Hole Sets	No. of 7/16" Hole Sets	Approx. Wt. (lbs.)
GBI1426TGBKT	1/4" x 2" x 6"	Copper	2	2	3
TGBI1426TGBKT	1/4" x 2" x 6"	Electro Tin Plated	2	2	3
GBI14210TGBKT	1/4" x 2" x 10"	Copper	4	3	4-1/2
TGBI14210TGBKT	1/4" x 2" x 10"	Electro Tin Plated	4	3	4-1/2
GBI14212TGBKT	1/4" x 2" x 12"	Copper	6	3	5
TGBI14212TGBKT	1/4" x 2" x 12"	Electro Tin Plated	6	3	5
GBI14216TGBKT	1/4" x 2" x 16"	Copper	8	3	6
TGBI14216TGBKT	1/4" x 2" x 16"	Electro Tin Plated	8	3	6
GBI14220TGBKT	1/4" x 2" x 20"	Copper	12	3	6-1/2
TGBI14220TGBKT	1/4" x 2" x 20"	Electro Tin Plated	12	3	6-1/2
GBI14224TGBKT	1/4" x 2" x 24"	Copper	14	5	7
TGBI14224TGBKT	1/4" x 2" x 24"	Electro Tin Plated	14	5	7

Description:

- 1/4" thick x 2" wide electrolytic tough pitch 110 alloy copper bar.
- 5/16" holes, 5/8" on center which accommodates "A" spaced 2 hole compression lugs.
- 7/16" holes, 1" on center which accommodates "C" spaced 2 hole compression lugs.
- Comes with 1-1/2" insulators and 1" offset stainless steel mounting brackets.
- Other sizes available. Contact factory for details.
- Includes one 1/2 oz. tube of antioxidant (#HCAJC1/2).
- Meets "BICSI" and EIA/TIA 607 standards.

Kits Include:

- (1) Ground bar with brackets and insulators
- (6) GECLB62A: #6 compression lug
- (3) GECLB22C: #2 compression lug
- (1) GECLB2/02C: 2/0 compression lug
- (12) CS46S: 1/4"-20 x 3/4" SS hex head cap screw
- (12) LW4S: 1/4"-20 SS lock washer
- (12) N420S: 1/4"-20 SS hex nut
- (6) CS68S: 3/8"-16 x 1" SS hex head cap screw
- (6) LW6S: 3/8"-16 SS lock washer
- (6) N616S: 3/8"-16 SS hex nut