


HammerHead Ground Rod Clamps

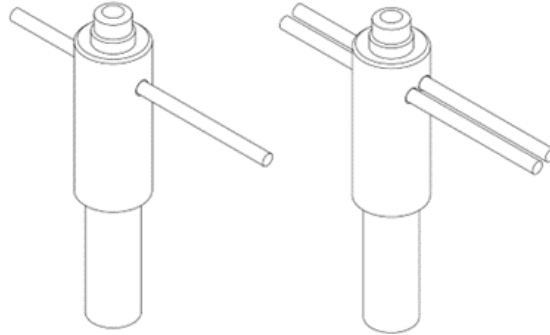

Description

- Made from highly conductive, corrosion resistant copper.
- Accommodates 1/2", 5/8", and 3/4" Copper Clad Ground Rods.
- Conductor size minimum size #6 Solid up to maximum 2/0 Stranded.
- Features a quick and simple installation design.
- Creates a permanent and irreversible connection.

Application

- Ground rod clamp for securing through cable(s) to ground rod.

Product Number	Ground Rod Size (Nominal)**	Conductor Range	Number of Conductors
HHGRC12F4S6S	1/2"	#6 Solid - #4 Solid	1
HHGRC12F4S6S-2	1/2"	#6 Solid - #4 Solid	2
HHGRC12F24	1/2"	#4 Stranded - #2 Stranded	1
HHGRC12F2/01/0	1/2"	1/0 Stranded – 2/0 Stranded	1
HHGRC5822S-2	5/8"	#2 Solid - #2 Stranded	2
HHGRC582/01/0	5/8"	1/0 Stranded – 2/0 Stranded	1
HHGRC344S6S	3/4"	#6 Solid - #4 Solid	1
HHGRC3424	3/4"	#4 Stranded - #2 Stranded	1
HHGRC342/01/0	3/4"	1/0 Stranded – 2/0 Stranded	1

** Copper-bonded steel ground rod size