



CPC Pipe Clamps



Industry Leading Design



CPC Pipe Clamps

- Wide conductor range; #6 Solid through 250 MCM.
- Also used for pedestal grounding.
- Silicon Bronze hardware available.
- * Electro Tin Plated Bronze includes stainless steel hardware.

- Dual UL Listing (UL96 and UL467).
- Acceptable for direct burial.
- Tamper Proof comes with break away nuts.



Tamper Proof

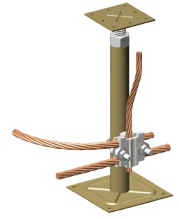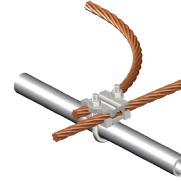


Pipe Range .5/.75

Part No.	Tamper Proof	Material	Nominal Pipe Size Range	Pipe Outside Diameter	Box Qty.	Approx. Box Wt. (lbs.)
CPC.5/.75	No	ETPB*	.5" - .75"	0.375" - 1"	5	2-1/2
CPC.5/.75TP	Yes	ETPB*	.5" - .75"	0.375" - 1"	5	2-1/2



Tamper Proof

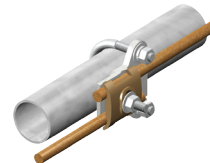



Pipe Range 1/1.25

Part No.	Tamper Proof	Material	Nominal Pipe Size Range	Pipe Outside Diameter	Box Qty.	Approx. Box Wt. (lbs.)
CPC1/1.25	No	ETPB*	1" - 1.25"	0.9375" - 1.7"	5	3
CPC1/1.25TP	Yes	ETPB*	1" - 1.25"	0.9375" - 1.7"	5	3

- Feature "quick connect", bi-directional design.
- Pressed stud design ensures a flush mounting surface.




Tamper Proof

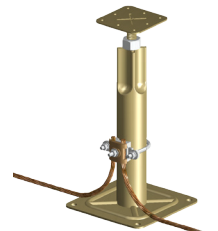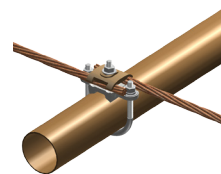


Pipe Range 1.5/2 - 5/6

Part No.	Tamper Proof	Material	Nominal Pipe Size Range	Pipe Outside Diameter	Box Qty.	Approx. Box Wt. (lbs.)
CPC1.5/2	No	ETPB*	1.5" - 2"	1.25" - 2.4"	5	3-3/4
CPC1.5/2TP	Yes	ETPB*	1.5" - 2"	1.25" - 2.4"	5	3-3/4
CPC2.5/3	No	ETPB*	2.5" - 3"	2.5" - 3.5"	5	5
CPC2.5/3TP	Yes	ETPB*	2.5" - 3"	2.5" - 3.5"	5	5
CPC3.5/4	No	ETPB*	3.5" - 4"	3.375" - 4.5"	5	6-1/4
CPC3.5/4TP	Yes	ETPB*	3.5" - 4"	3.375" - 4.5"	5	6-1/4
CPC5/6	No	ETPB*	5" - 6"	4.75" - 6.63"	5	8-3/4
CPC5/6TP	Yes	ETPB*	5" - 6"	4.75" - 6.63"	5	8-3/4


- Feature "quick connect", bi-directional design.
- Pressed stud design ensures a flush mounting surface.

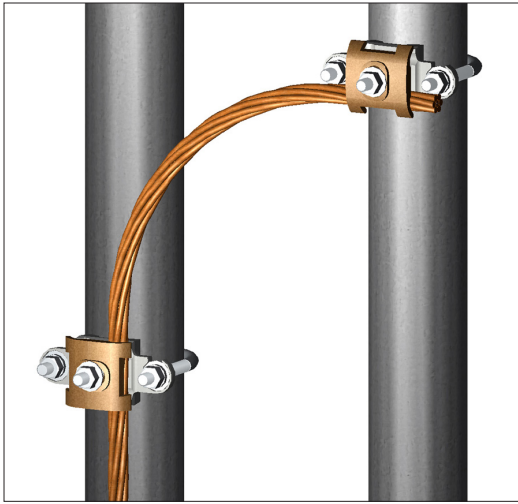


Bi-directional Design

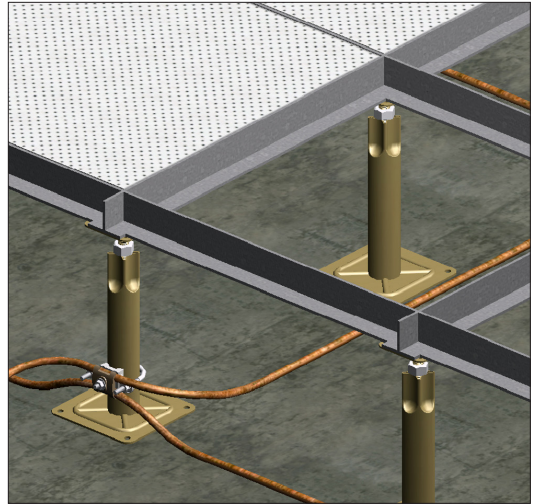


SRG Application

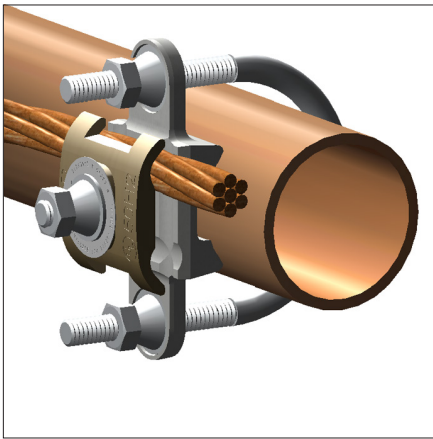

Tamper Proof: Step 1

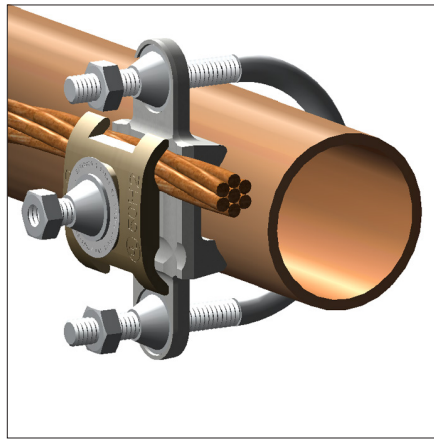


Tamper Proof: Step 2

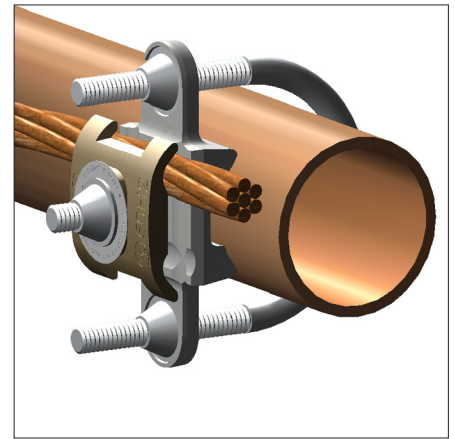

Completed Installation



Fence Post Application

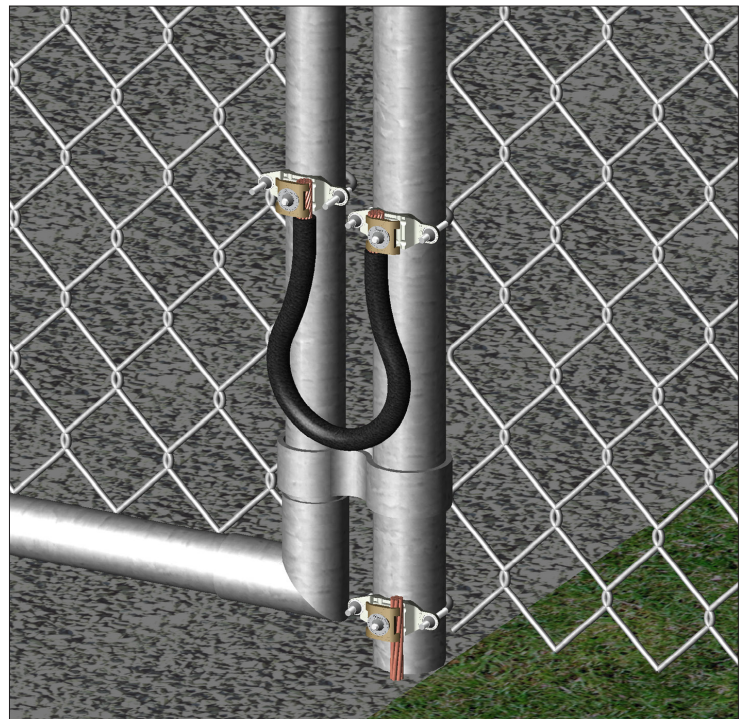




Fence Gate Application



CPC Cross Reference

Pipe Ground Clamps

Harger's CPC Series of Pipe Ground Clamps reduce inventory and increase profits by providing greater range taking capacity. Harger's 6 CPC Pipe Clamps replace up to 93 different BURNDY® Series Clamps. Only Harger's CPC Series Clamps are UL listed for both electrical grounding and lightning protection.

	Harger Part	BURNDY® GAR Part	BURNDY® GD Part	BURNDY® GP Part	Harger Conductor Range	Harger Actual OD Range			
	CPC.5/1.75	GAR114C*		GP114C*	#6 Solid - 250 MCM	0.375" - 1"			
		GAR1126		GP1126					
		GAR1129		GP1129					
		GAR644C*		GP644C*					
		GAR6426		GP6426					
		GAR6429		GP6429					
		GAR144C*		GP144C*					
		GAR1426		GP1426					
		GAR1429		GP1429					
	CPC1/1.25	GAR144C*		GP144C*	#6 Solid - 250 MCM	0.9375" - 1.7"			
		GAR1426		GP1426					
		GAR1429		GP1429					
		GAR154C*							
		GAR1526	GD1526						
		GAR1529	GD1529						
		GAR164C*		GP164C*					
		GAR1626	GD1626						
		GAR1629	GD1629	GP1629					
	CPC1.5/2	GAR154C*			#6 Solid - 250 MCM	1.25" - 2.4"			
		GAR1526	GD1526						
		GAR1529	GD1529						
		GAR164C*		GP164C*					
		GAR1626	GD1626						
		GAR1629	GD1629	GP1629					
		GAR174C*	GD174C*						
		GAR1726	GD1726	GP1726					
		GAR1729	GD1729						
		GAR184C*	GD184C*	GP184C*					
		GAR1826	GD1826	GP1826					
				GAR1829			GD1829		
		CPC2.5/3	GAR194C*	GD194C*				#6 Solid - 250 MCM	2.5" - 3.5"
			GAR1926	GD1926					
GAR1929	GD1929								
GAR204C*	GD204C*								
GAR2026	GD2026		GP2026						
GAR2029	GD2029								
CPC3.5/4	GAR214C*	GD214C*		#6 Solid - 250 MCM	3.375" - 4.5"				
	GAR2126	GD2126							
	GAR2129	GD2129							
	GAR224C*	GD224C*							
	GAR2226	GD2226	GP2226						
	GAR2229	GD2229							
CPC5/6	GAR244C*			#6 Solid - 250 MCM	4.75" - 6.63"				
	GAR2426								
	GAR2429								
	GAR8629								

BURNDY® is a registered trademark of FCI-BURNDY Products

*BURNDY® Part # has a #8 Solid minimum

Harger Lightning & Grounding

301 Ziegler Drive, Grayslake, IL 60030
847.548.8700 • 800.842.7437
www.harger.com • hargersales@harger.com

